


TYPE 5CCEG

For Reflow Soldering 适合回流焊接
Frequency Range 频率范围： 20 ~ 120 MHz
Inductance Range 电感值范围： 0.05 ~ 2.7 μH
Q Approx 概略Q值： 70 (at 100MHz)

Recommended patterns
推荐焊盘尺寸

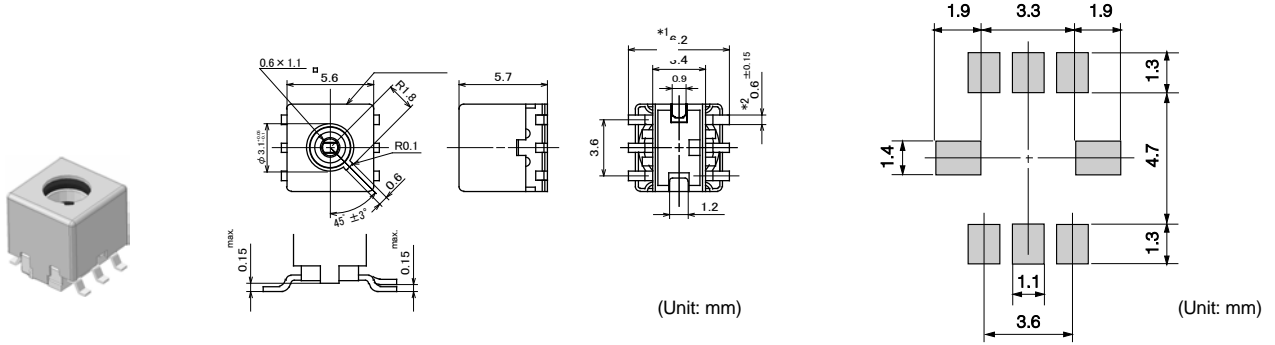

Features

- High reliability conforms to automotive applications.
- AEC-Q200 compliant.

特点

- 符合车载使用的高可靠性
- 符合AEC-Q200

Applications

- Suitable as a RF matching transformer for car tuner.
- Operating temperature (-40~+85°C)

应用


- 适用于车载音响调谐器用的射频匹配变压器
- 使用温度范围：-40 ~ +85°C

SELECTION GUIDE FOR STANDARD TRANSFORMERS


TYPE 5CCEG

零件号码	测试频率	C可变范围	Q	内部连接 *
Part Number	Test Frequency (MHz)	C Range (pF)	Unloaded Q	Winding Connection *
#A1313AN-0001GGH=P3	100	11.4 +3/-3%	72 +/-20%	A
#A1313AN-0002GRG=P3	100	11.4 +5/-2%	61 +/-20%	B
#A1313AN-0003GRG=P3	100	11.4 +2/-4%	54 +/-20%	B
#A1313AN-0004GGH=P3	100	11.7 +3/-3%	72 +/-20%	A

*Connection A (Bottom View)

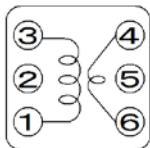

* Connection B (Bottom View)

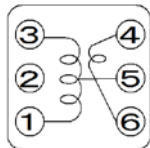

5CCEG type is customized item. Please feel free to contact us for details.
5CCEG 型号是按客户规格订制生产的产品。敬请咨询详细信息。

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Murata:](#)

[#A1313AN-0001GGH=P3](#) [#A1313AN-0003GRG=P3](#) [#A1313AN-0004GGH=P3](#) [#A1313AN-0002GRG=P3](#)